



Quality Products. Service Excellence.

Class 2 Energy Limiting Small Box Mount BA-C-D-E Series


Features



- Used in chimes, door bells, security systems, decorative lighting, furnaces, humidifiers, appliances, vending machines, intercom system type applications.
- Rugged, low noise, cool running design, indoor use only.
- Stripped wire input (primary) leads, screw terminal/quick fit tab terminal output (secondary).
- Nipple locknut mount for box installation, complete with locknut and mounting bracket (as shown below).
- Input leads are black, on 240V models 240V lead is red. All models are 60 Hz.- inherently limited - no fuses or circuit breakers.
- UL listed #E184371 - EXCEPT for part numbers BE2F & BE7G.
- CSA certified (209651)



Gallery

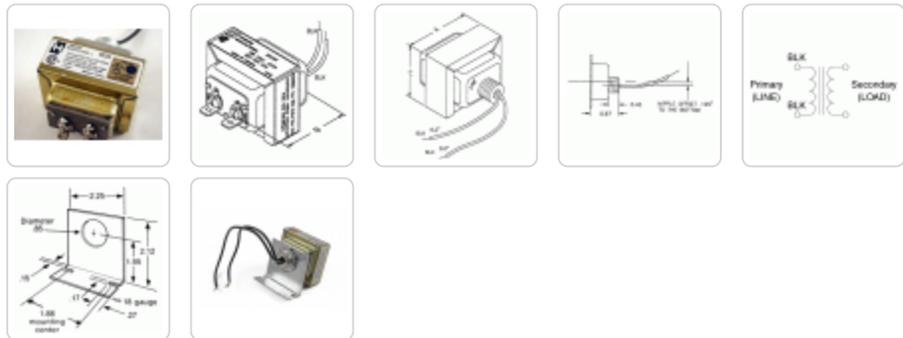

Accessories

- Mounting Bracket

| Part No. | A.C. Input (Primary) | A.C. Output Secondary (RMS) | | Power Rating | | Overall Dimensions | | |
|----------|-------------------------|--------------------------------|-------|-----------------|------|--------------------|------|------|
| | V (RMS) | V | A | VA | Note | A | B | C |
| BA2DA | 120 | 10 | 0.5 | 5 | * | 2.33 | 2.22 | 1.98 |
| BC2DA | 120 | 10 | 1.2 | 12 | * | 2.33 | 2.22 | 1.98 |
| BC2F | 120 | 16 | 0.75 | 12 | * | 2.33 | 2.22 | 1.98 |
| BC2G | 120 | 24 | 0.5 | 12 | * | 2.33 | 2.22 | 1.98 |
| BD2E | 120 | 12 | 1.67 | 20 | * | 2.33 | 2.34 | 1.98 |
| BD2EE | 120 | 14 | 1.43 | 20 | * | 2.33 | 2.34 | 1.98 |
| BD2F | 120 | 16 | 1.25 | 20 | * | 2.33 | 2.34 | 1.98 |
| BD2FF | 120 | 18 | 1.11 | 20 | * | 2.33 | 2.34 | 1.98 |
| BD2G | 120 | 24 | 0.833 | 20 | * | 2.33 | 2.34 | 1.98 |
| BE2F | 120 | 16.5 | 2.42 | 40 | * | 2.33 | 2.60 | 1.98 |
| BE2G | 120 | 24 | 1.67 | 40 | * | 2.33 | 2.60 | 1.98 |
| BD5F | 240 | 16 | 1.25 | 20 | * | 2.33 | 2.34 | 1.98 |
| BD5G | 240 | 24 | 0.83 | 20 | * | 2.33 | 2.34 | 1.98 |
| BE5G | 240 | 24 | 1.67 | 40 | * | 2.33 | 2.60 | 1.98 |

| Part No. | A.C. Input (Primary) | A.C. Output Secondary (RMS) | | Power Rating | | Overall Dimensions | | |
|----------|-------------------------|--------------------------------|------|-----------------|------|--------------------|------|------|
| | V (RMS) | V | A | VA | Note | A | B | C |
| BE5DG | 208/240 | 24 | 1.67 | 40 | * | 2.33 | 2.60 | 1.98 |
| BE7G | 347 | 24 | 1.67 | 40 | - | 2.33 | 2.60 | 1.98 |

Note: * = 105 degree temperature design

Tags: **class 2, small box, indoor, security, lighting, door, appliances, vending, intercom**

Data subject to change without notice

© 2026. Hammond Manufacturing Ltd. All rights reserved.